



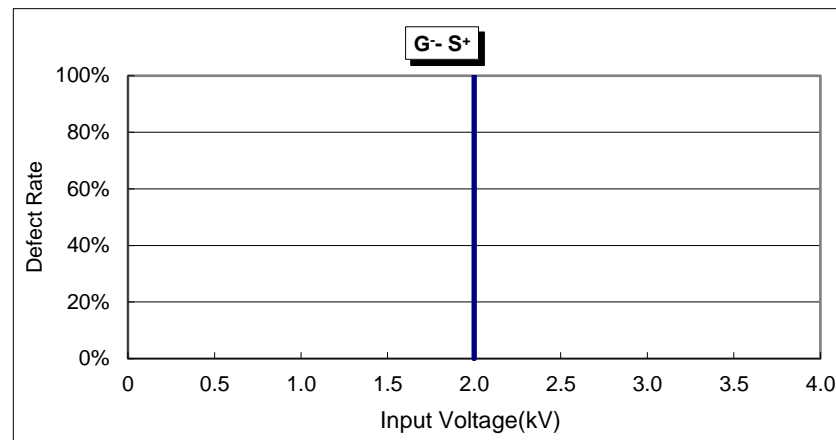

# Test Result of Electrical Static Discharge (Machine Model) [ Reference Data ]

Products	SiC module	Part No.	BSM120D12P2C005	Measurement Instrument	ESS-606 AT-T700 (Noise Laboratory co.,ltd)	Measurement Condition	C=200pF R=0Ω Ta=25°C
----------	------------	----------	-----------------	------------------------	---	-----------------------	-------------------------


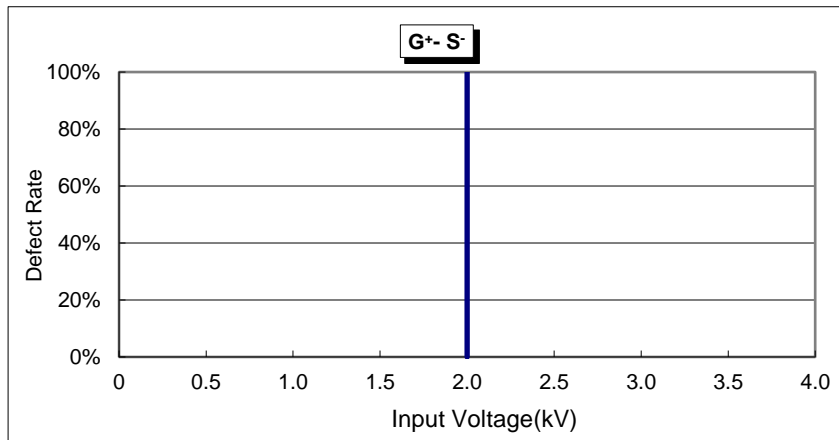


(Notice) This data is made from representative value of a specific lot. The data indicates neither the worst nor guaranteed value.



# Test Result of Electrical Static Discharge (Human Body Model) [ Reference Data ]

Products	SiC module	Part No.	BSM120D12P2C005	Measurement Instrument	ESS-606 AT-T700 (Noise Laboratory co.,ltd)	Measurement Condition	C=100pF R=1.5kΩ Ta=25°C
----------	------------	----------	-----------------	------------------------	---	-----------------------	----------------------------

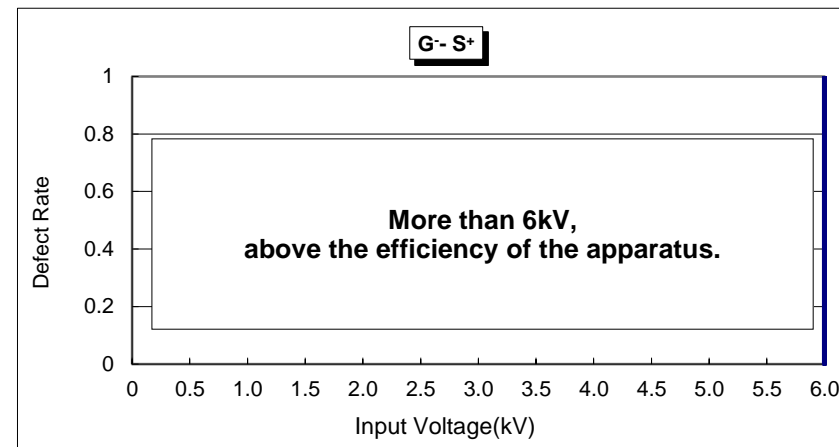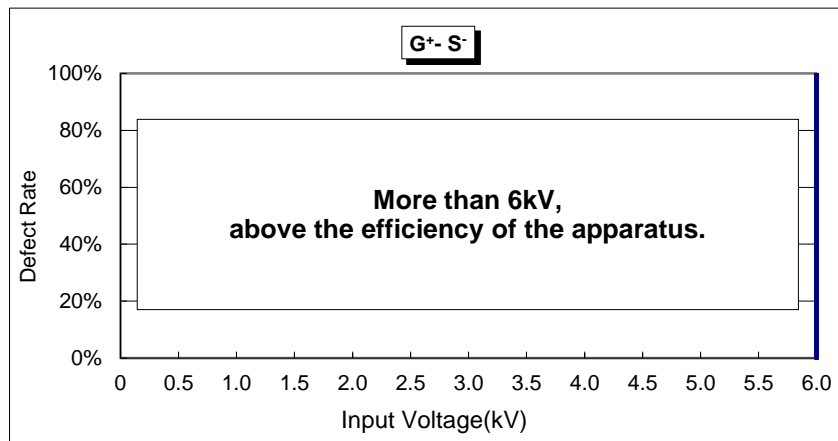

(Notice) This data is made from representative value of a specific lot. The data indicates neither the worst nor guaranteed value.