

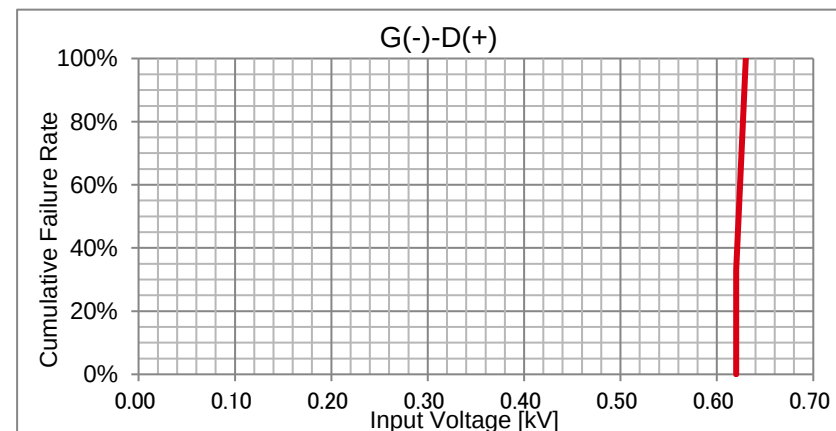
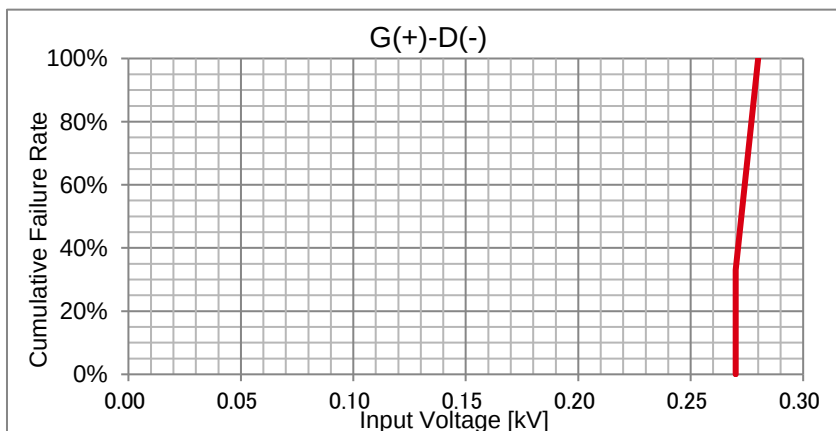


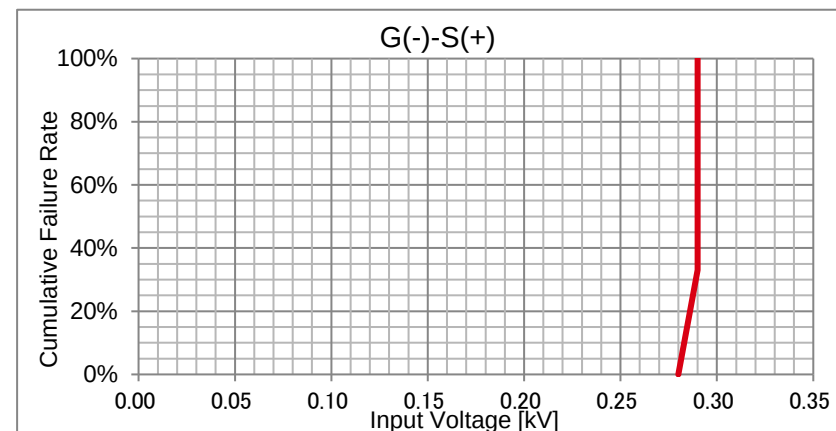

Test Result of Electrical Static Discharge (Machine Model) [Reference Data]

Products	SiC MOSFET	Part No.	SCT2160KE	Measurement Instrument	ESS-606 AT-T700 (Noise Laboratory co.,ltd)	Measurement Condition	C=200 pF R=0 Ω T _a =25°C
----------	------------	----------	-----------	------------------------	---	-----------------------	---

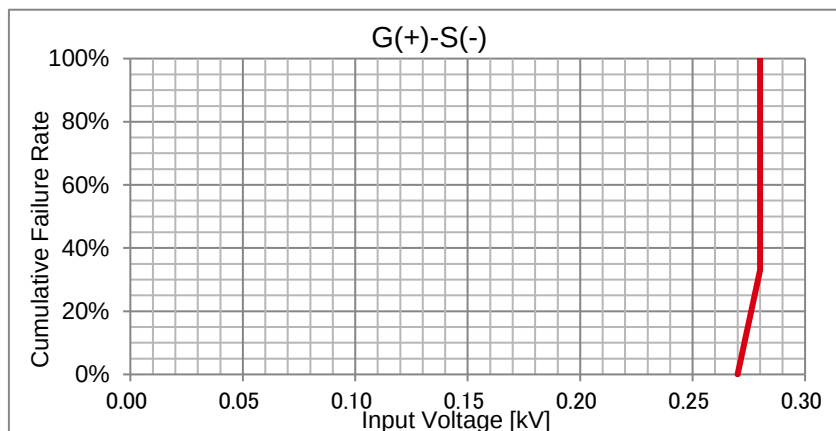





(Notice) This data is made from representative value of a specific lot. The data indicates neither the worst nor guaranteed value.

SCT2160KE_MM



Test Result of Electrical Static Discharge (Human Body Model) [Reference Data]

Products	SiC MOSFET	Part No.	SCT2160KE	Measurement Instrument	ESS-606 AT-T700 (Noise Laboratory co.,ltd)	Measurement Condition	C=100 pF T _a =25°C	R=1.5 kΩ 5 pulses
----------	------------	----------	-----------	------------------------	---	-----------------------	----------------------------------	----------------------

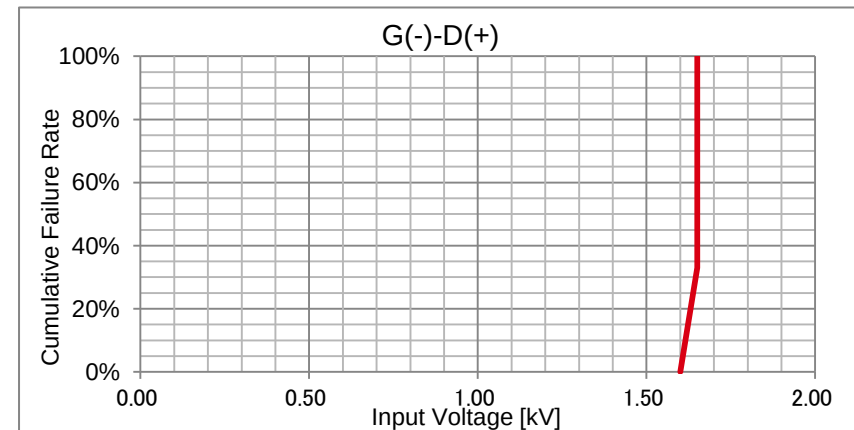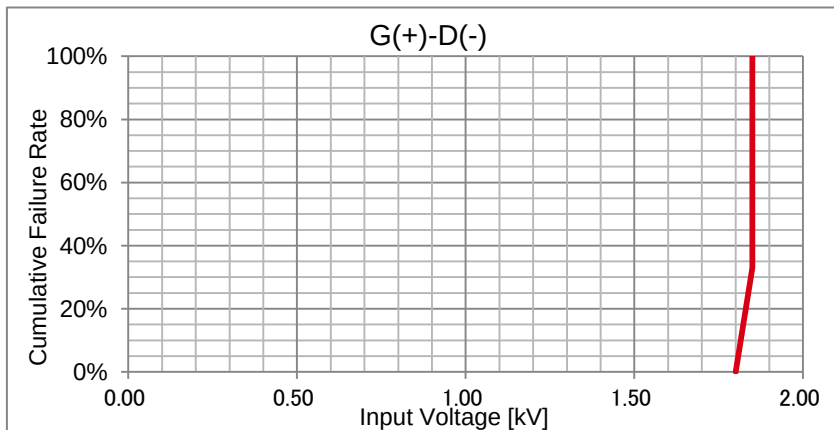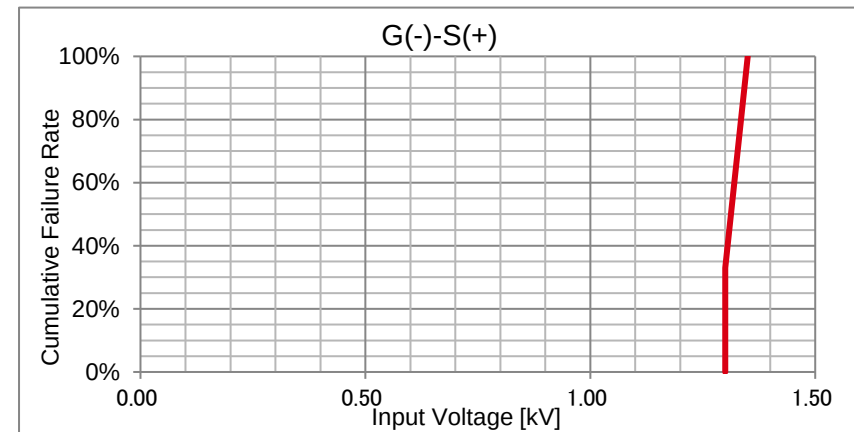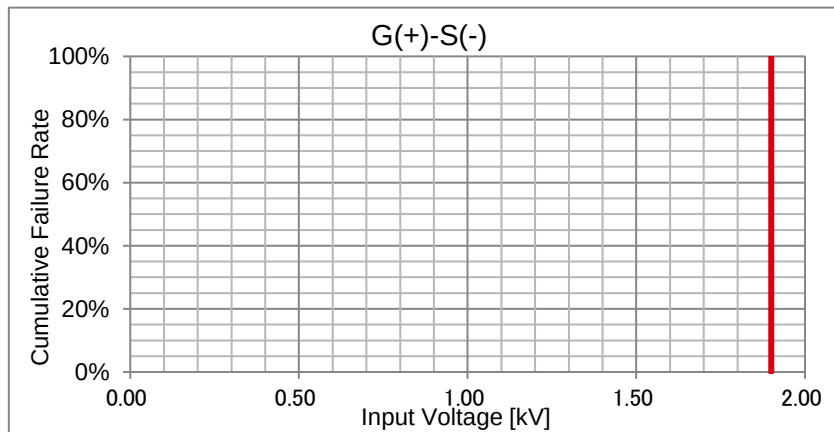

(Notice) This data is made from representative value of a specific lot. The data indicates neither the worst nor guaranteed value.

SCT2160KE_HBM